


VOLA FS2












Fitting instruction
Montageanleitung
Monteringsvejledning




Monteringsvægledning
Montage hanledning
Manuel de montage

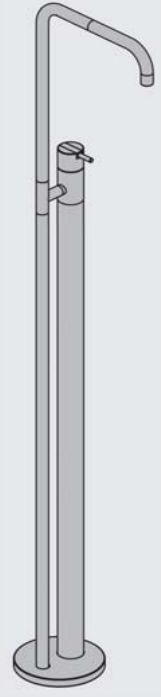

vola

Data, 3 Bar (Max. 5 Bar):
l/min. Gal/min.
9 2.4
Max. 65°C, 150°F

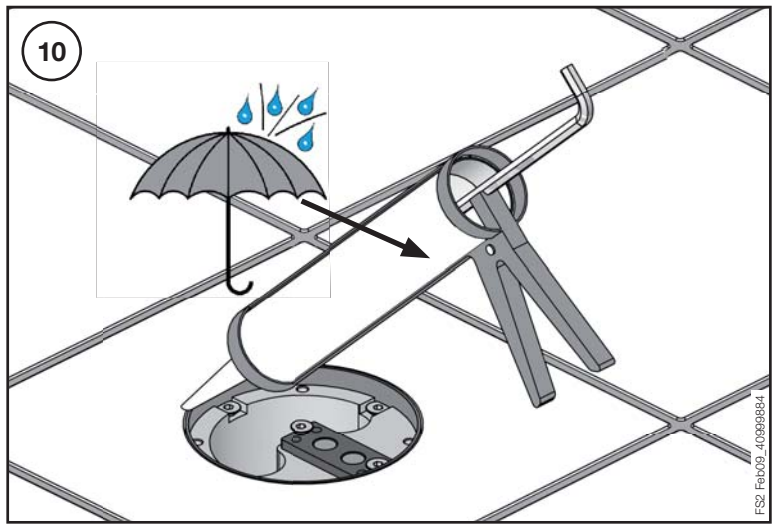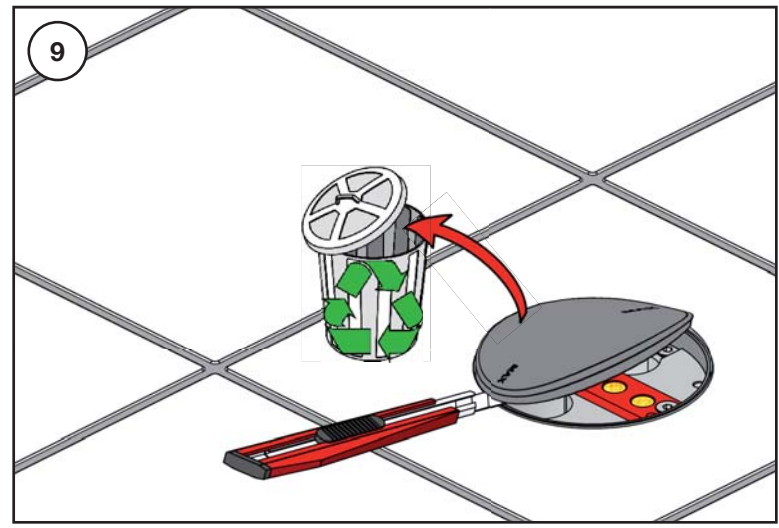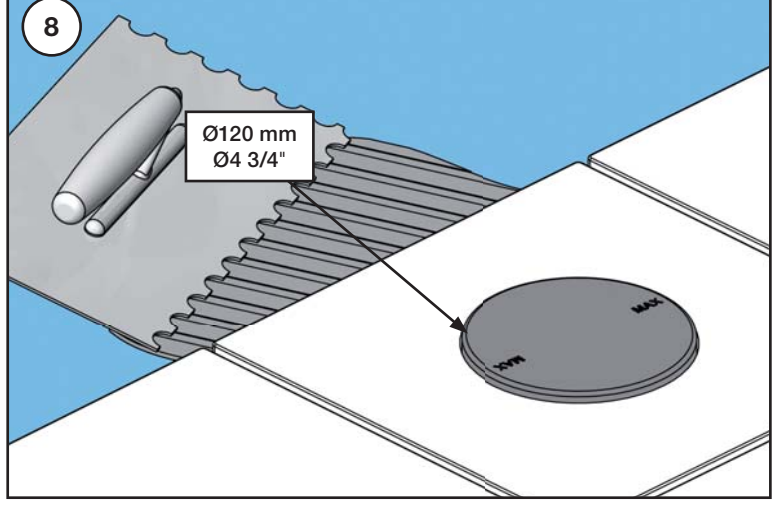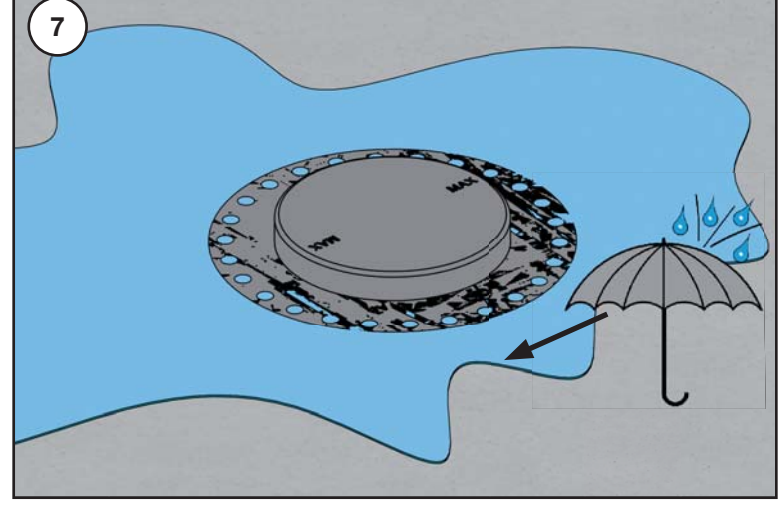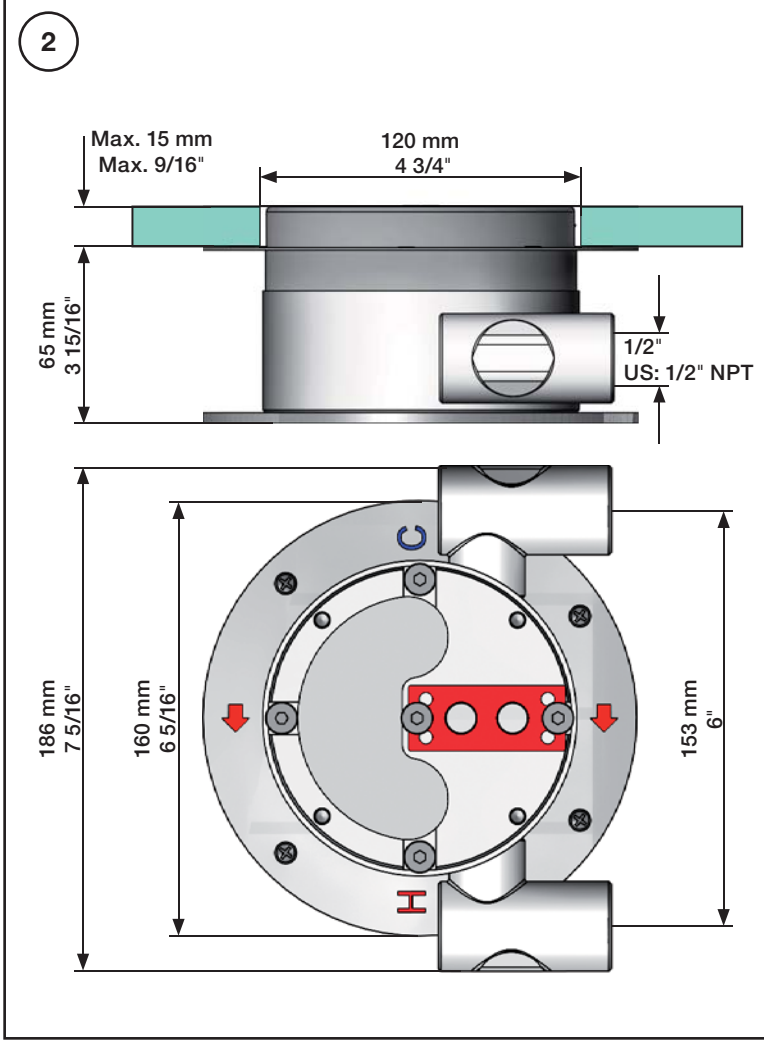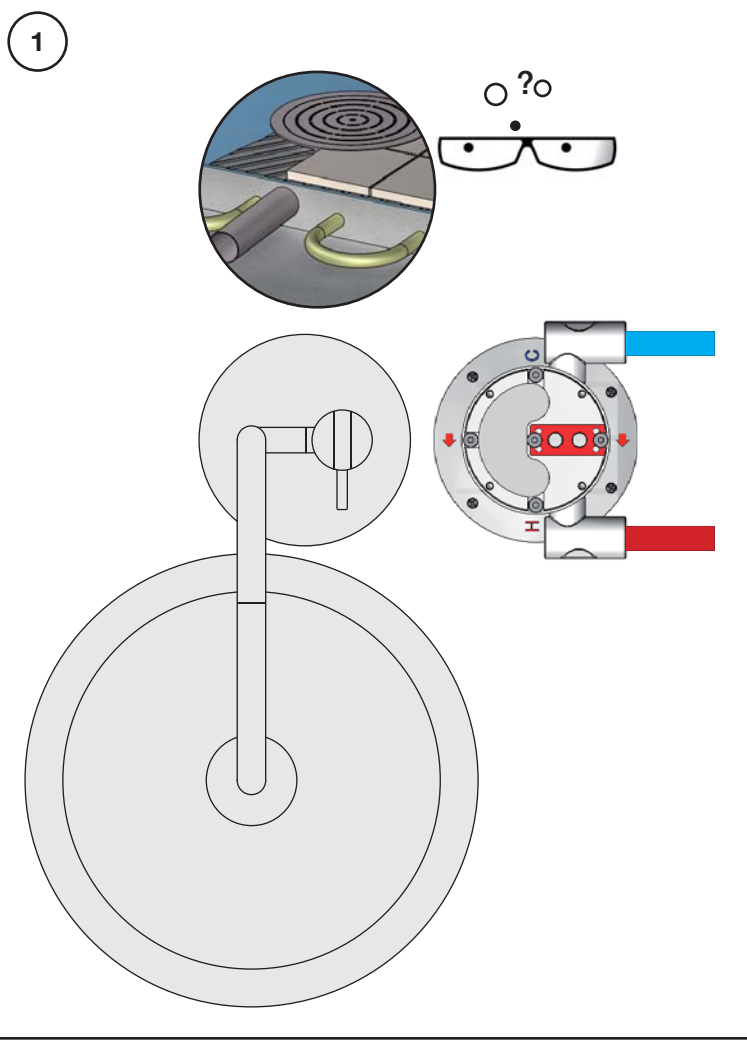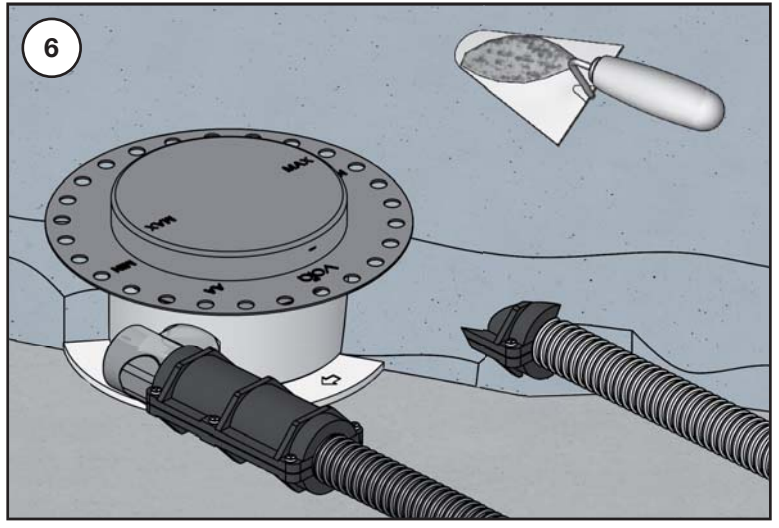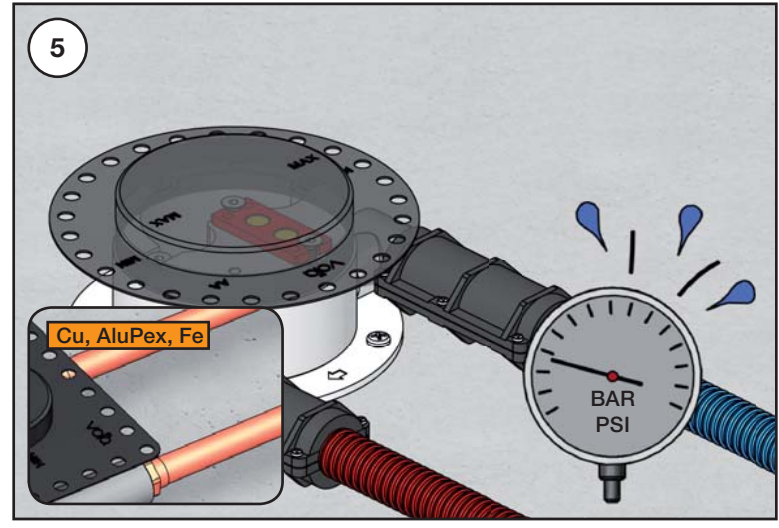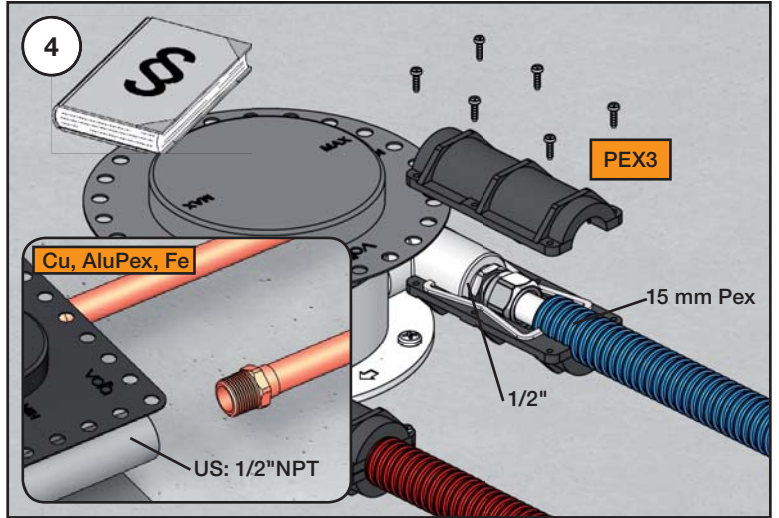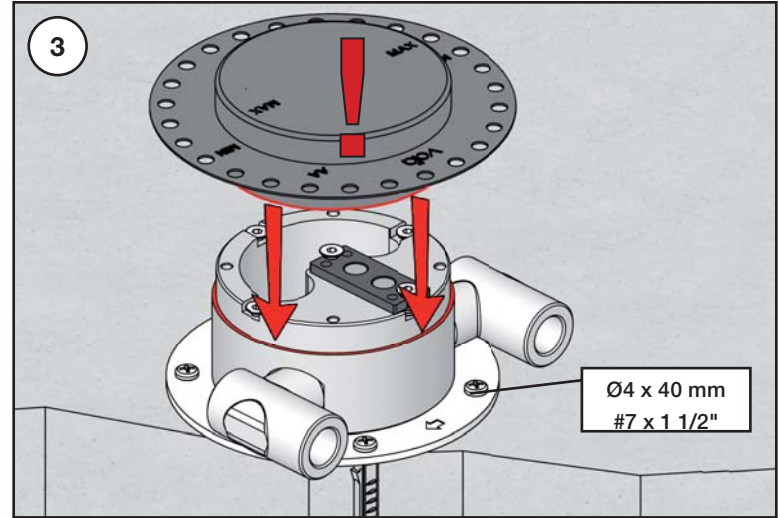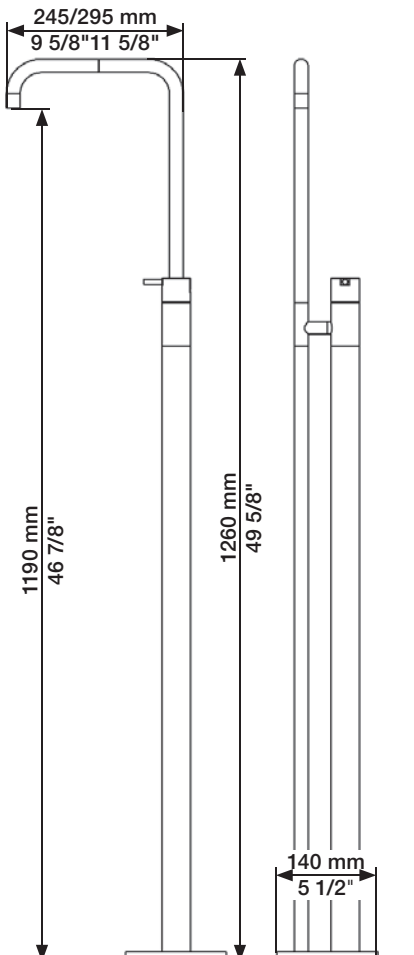

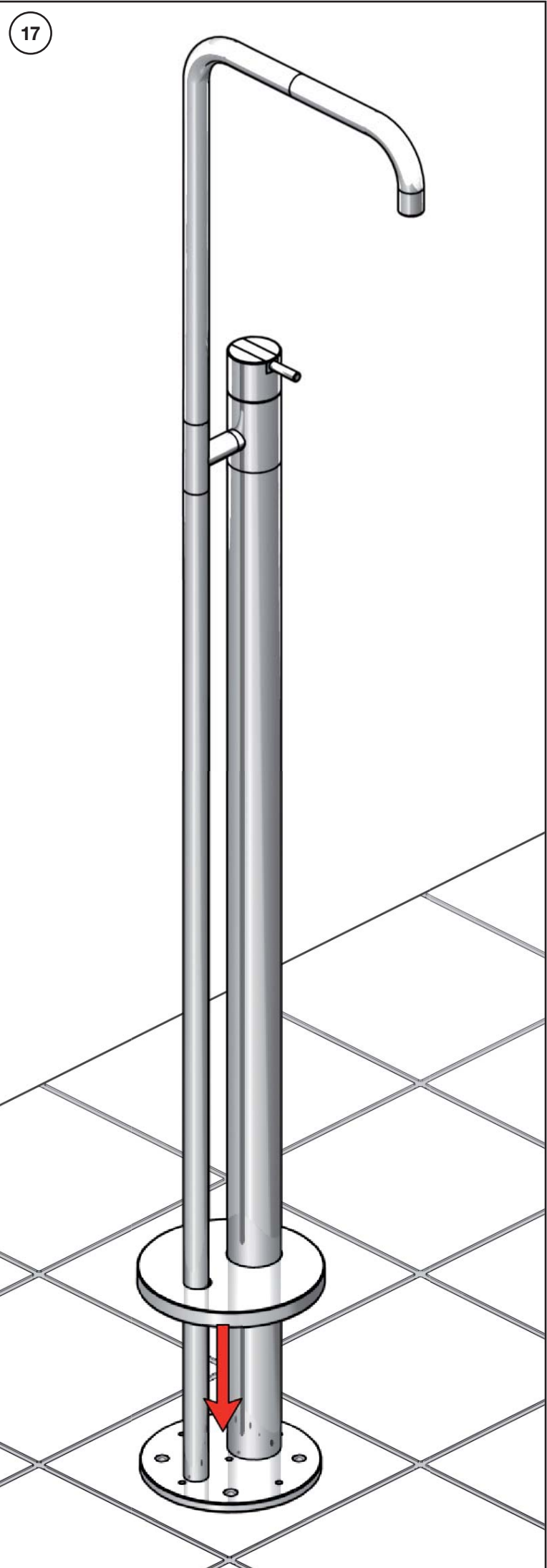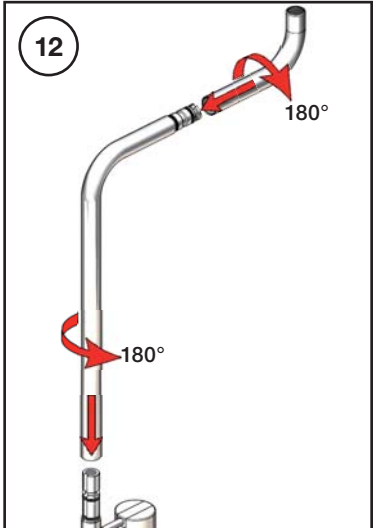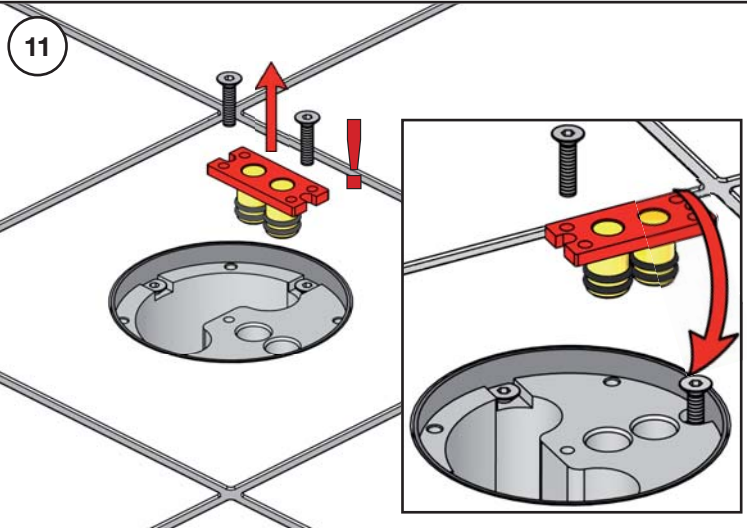

Extension Verlängerung Forlængelse	Förlängning Verlængstücken Modification
X: 3 - 15 mm 2/16" - 9/16"	Standard
15 - 25 mm 9/16" - 1"	VR1396+15
25 - 35 mm 1" - 1 3/8"	VR1396+30

